

Computer Cables & Accessories

Contents

HDMI™ & DVI PRODUCTS	68
DVI PRODUCTS	69
DETACHABLE VIDEO CABLE	70
VGA VIDEO CABLE	71
VKM CABLES (Video - Keyboard - Mouse Combo).....	72
RGB, CCTV & CATV CABLE	73
USB CABLES	74
USB PRODUCTS.....	75-76
COMPUTER CABLE ASSEMBLIES.....	77-81
ADAPTOR CABLES & BULK CABLE	82
DISK DRIVE CABLES.....	83
INTERNAL CABLES & CPU COOLER FANS.....	84
BRACKETS & BRACKET CABLES	85
EXTERNAL SCSI CABLES	86
SCSI TERMINATORS & ADAPTORS	87
MISCELLANEOUS.....	88
PASSIVE ADAPTORS	89-90
LOW PROFILE PASSIVE ADAPTORS	91-92
DATA SWITCH BOXES	93-95
DATA SWITCH BOXES & ACTIVE DEVICES.....	96
ACTIVE DEVICES & AUDIO / VIDEO ACCESSORIES	97
AUDIO / VIDEO ACCESSORIES	98-100



HDMI™ & DVI PRODUCTS

HIGH DEFINITION MULTIMEDIA INTERFACE

- Pass Uncompressed Digital Video Stream and Up to 8 Channels of Digital Audio.
- Backwards Compatible with DVI Digital.
- Gold Plated Contacts.

HDMI™ Male to Male

S-HDI2-(XX)



Length in Meters (XX): 1, 2, 3, 5, 8, 11, 15, 23. (1 Meter $\approx$ 3.28ft)

HDMI™ Male to DVI Male

S-HDI-DVI-(XX)



Length in Meters (XX): 1, 2, 3, 5. (1 Meter $\approx$ 3.28ft)

HDMI™ Male to Female (Extension)

S-HDI-MF-(XX)



Length in Meters (XX): 1, 2, 3, 5. (1 Meter $\approx$ 3.28ft)

HDMI™ KIT


- Gold Plated Contacts.
- Solder Type.

HDI-19P-KIT

BULK CABLE

- 5 Pairs + 5 Conductors.
- 30 AWG Conductors.

MCC-HDI-5P5-500 500ft. Roll

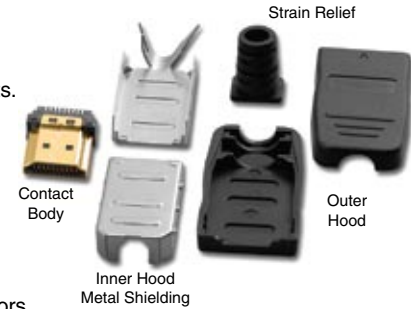

VARIOUS ADAPTORS


- 19 Contacts Fully Loaded.
- Gold Plated Conductors.
- Backwards Compatible with DVI Digital.

HDMI™ ADAPTORS

<u>AD-HDI-19FF</u>	Female to Female
<u>AD-HDI-19MF</u>	Male to Female
<u>AD-HDI-19MM</u>	Male to Male

HDMI™ to DVI ADAPTORS

<u>AD-HDIF-DVIM</u>	HDMI™ Female to DVI Male
<u>AD-HDIM-DVIF</u>	HDMI™ Male to DVI Female

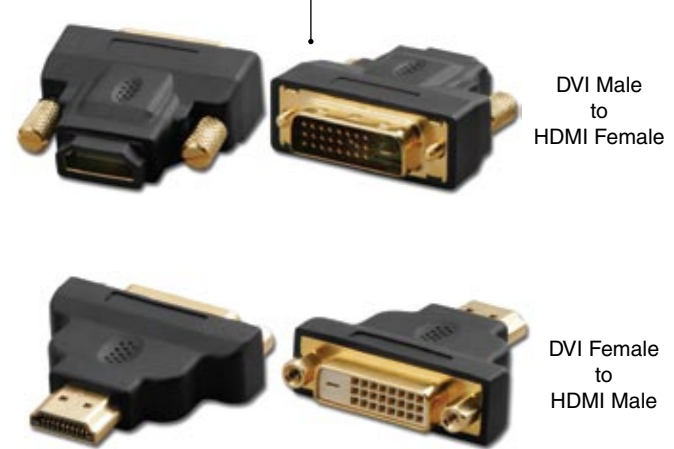



PARALLEL PRINTER CABLES

- RS232 25 Pin Male to Centronic 36 Pin Male
- Molded w/ Thumb Screw
- Full Length Mylar Foil Shield
- 25 Wires; 26 AWG Stranded Conductors, an absolute must for bidirectional parallel port
- Ground Indented D-SUB Connectors



RS232 Male to Centronic Male

S-36M25M-(LL)'

LL= Length(ft): 2, 6, 10, 15, 25, 50, 100.

R = Right Angle (Exit Right)

S-36M25M-(LL)'R

L = Left Angle (Exit Left)

S-36M25M-(LL)'L

LL= Length(ft): 6, 10, 15.



CENTRONIC CABLES (Parallel)

- Centronic 36 Pin Connectors
- Full 36 Conductors; Wired Straight Through
- 26 AWG Stranded Conductors
- Molded, Mylar Foil Shielded Cable



Male to Female

Male to Male


S-36MF-18"

S-36MF-6'

S-36MF-10'

S-36MM-6'

S-36MM-12'

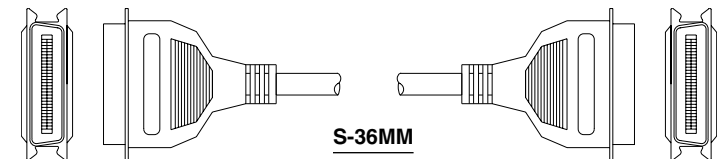

RS232 25 PIN CABLES (Serial)

- RS232 Dual 25 Pin
- Molded w/ Thumb Screw
- Full Length Mylar Foil Shield
- Fully Wired Straight Thru, 26 AWG Stranded Conductors
- For PC Serial Port and/or RS232 Type Applications
- Ground Indented D-Sub Plugs



25 Pin Male to Female

S-25MF-(LL)'

25 Pin Male to Male


S-25MM-(LL)'

LL= Length(ft): 2, 3, 6, 10, 15, 25, 50, 100.

25 Pin Female to Female

S-25FF-(LL)'

LL= Length(ft): 2, 6, 10, 25, 50, 100.

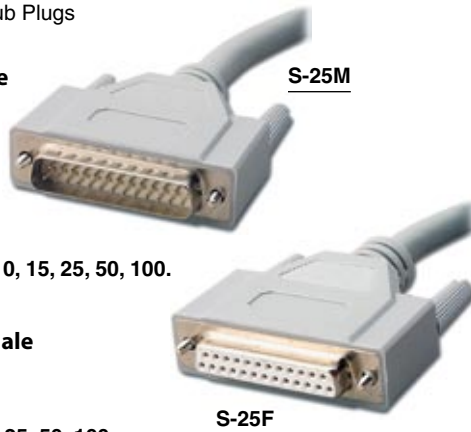

RS232 9 PIN CABLES (Serial)

- RS232 Dual 9 Pin
- Molded w/ Thumb Screw
- Full Length Mylar Foil Shield
- Fully Wired Straight Thru, 26 AWG Stranded Conductors
- For PC Serial Port and/or RS232 Type Applications
- Ground Indented D-Sub plugs



9 Pin Male to Female

S-9MF-(LL)'

9 Pin Male to Male


S-9MM-(LL)'

LL= Length(ft): 3, 6, 10, 15, 25, 50, 100.

9 Pin Female to Female

S-9FF-(LL)'

LL= Length(ft): 3, 6, 10, 25, 50.

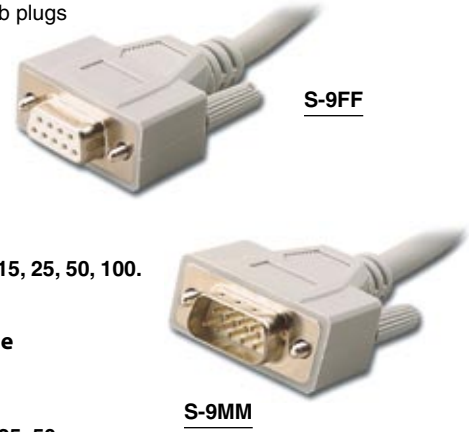


AT SERIAL ADAPTOR CABLES

- RS232 25Pin to 9 Pin
- Adapts Serial Port to RS232 Devices, i.e Modems, Printers
- Molded w/ Thumb Screws
- 9 Wires; 26 AWG Stranded Conductors
- Full Length Mylar Foil Shielded



	1	2	3	4	5	6	7	8	9	DB9
PIN OUT										
DB25	8	3	2	20	7	6	4	5	22	

S-25M9F

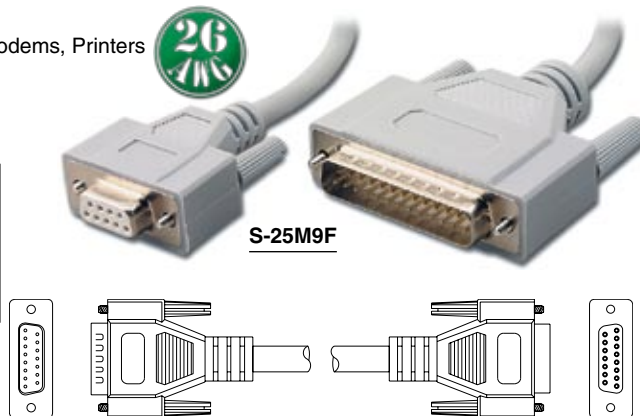

25 Pin Male to 9 Female

S-25M9F-(LL)'

LL= Length(ft): 1, 3, 6, 10, 15, 25.

25 Pin Male to 9 Male

S-25M9M-(LL)'

LL= Length(ft): 3, 6, 10, 15, 25.

25 Pin Female to 9 Female

S-25F9F-(LL)'

LL= Length(ft): 3, 6, 10.