




- Home
- Products
- Online Catalog
- Request Quote
- Order Online
- Check Stock
- Request Print Catalog
- Request Samples
- Engineering Data
- Distributors
- Capabilities Brochure

CALL NOW:
203 888-2133



Home > 1/4 Hex Female Standoffs

1/4 HEX FEMALE STANDOFFS

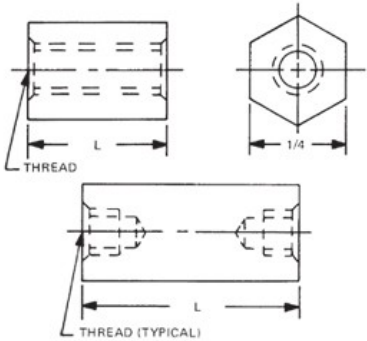

[Home](#) [Previous](#) [Next](#)
[Related Metric](#)

Ordering Code			
xxxxx	xxx	xx	x
Length	Thread	Material	Finish

PART: 2109 632 B

Red ?'s show missing selections. [Help](#)

[Thread depth information](#)
[Material Specifications](#)
[Ordering non-standard items](#)
[Request a Drawing](#)

Add to Cart

Qty1 *

Qty2

Qty3

	2105	9/16
☐	2105T	19/32
☐	2106	5/8
☐	2106T	21/32
☐	2107	11/16
☐	2107T	23/32
☐	2108	3/4
☐	2108T	25/32
☒	2109	13/16
☐	2109T	27/32
☐	2110	7/8
☐	2110T	29/32
☐	2111	15/16
☐	2111T	31/32

Thread *		
Select	Code	Thread
☐	440	4-40
☒	632	6-32
☐	832	8-32
☐	1032	10-32

Material *			
Select	Code	Material	RoHS
☐	AL	Aluminum	YES
☒	B	Brass	YES
☐	SS	Stainless Steel	YES
☐	S	Steel	YES
☐	N	Nylon	YES

Finish *

☒	Plain Finish
☐	1-Cad clear chromate/commercial*
☐	2-Cad clear chromate*
☐	3-Cad yellow chromate*
☐	4-Chrome over nickel
☐	5-Nickel
☐	6-Gold iridite
☐	7-Clear iridite
☐	9-Alodine 1200*
☐	10-Bright chrome
☐	11-Satin chrome
☐	12-Zinc