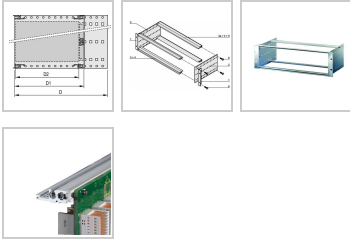


EuropacPRO kit, flexible design, unshielded, for backplane mounting

SCHROFF



Other Views



Catalog Number: 24563-132

[Back To Product](#)

- Aluminum construction
- Rear horizontal rail for backplane mounting with insulation strip
- EMC of approximately 40 dB at 1 GHz, 30 dB at 2 GHz, assuming that the front is covered with shielded front panels. Testing in accordance with VG 95373 part 15 or IEC 61587-3
- IP 20, in accordance with IEC 60529
- Modifications such as cutouts, different finishes or dimensions available
- Supplied as space-saving flat-pack
- Horizontal rail type "light"
- Internal and external dimensions in accordance with: IEC 60297-3-100, -101, IEEE 1101.1
- Subrack with side panel type F ("flexible"), Front 19" bracket included, depth-adjustable 19" bracket sold separately

Note:

Individual configuration: large variety of variants in height, width and depth; various guide rails for a wide variety of applications; Interior options; accessories and mounting material

Load:

Up to 11 kg

Shock/vibration:

Up to 2 g

Design:

EuropacPRO, Flexible

EMC Shielding:

- Unshielded
- Retrofitable

Type:

Subrack Kit

Description:

unshielded

Select product specifications before modifying or adding to project list or requesting a quote.

Height-U-defining

Depth-mm-defining

[Clear Selection](#)

Quantity

Add Item to Project List +

Documents

-  Main Catalog - EuropacPRO
-  User Manual

Links

-  Test report
-  Native CAD files

 
 
 
Technical Data

Depth mm	235.0
Depth D1 mm	175/235
Height U	3
Width HP	84

Delivery Comprises:

Item	Quantity	Description
1	2	19" support bracket for EMC sealing (stainless steel)
2	2	Side panel type F

Item	Quantity	Description
3a	2	Front horizontal rail (L-KD)
3b	2	Rear horizontal rail (L-ST) for backplane mounting with insulation strip
4	4	Threaded inserts, front and rear (pre-fitted)
5	2	Insulation strip (pre-fitted)
6	1	Assembly kit
7	1	User manual

Accessories		
	Perforated rail for connector according to EN 60603-2 (DIN 41612), 84 HP, with thread M2.5, PU 4 pieces	20822-048
Add Item to Project List +		
	Guide rails, standard, 160 mm deep, PBT, UL 94 V-0, red, groove width 2 mm, PU 10 pieces	24560-351
Add Item to Project List +		
	Guide rails, standard, 220 mm deep, PBT, UL 94 V-0, red, groove width 2 mm, PU 10 pieces	24560-353
Add Item to Project List +		
	Cover plate standard, 160 mm deep, Al, 1.2 mm, perforated, to push into light horizontal rail, PU 2 pieces	24561-051
Add Item to Project List +		
	Cover plate standard, 220 mm deep, Al, 1.2 mm, perforated, to push into light horizontal rail, PU 2 pieces	24561-052
Add Item to Project List +		
	19'' fixing material kit (screw, washer, nut), (8 x screws, 8 x plastic washers, 8 x cage nuts)	21100-435
Add Item to Project List +		

EXPLORE	CONTACT	DOWNLOAD
About Us	Customer Service	Download Center
Services & Capabilities	Find a Sales Office or Distributor	Reference Projects
News & Events	Global Locations	Videos
Newsletter Subscriptions	Product Compliance & Certifications	Product Configurators
Strategic Partnerships	Partner Login	Warranties and Terms of Sale & Procurement
Investor Relations		

Connect With Us

