
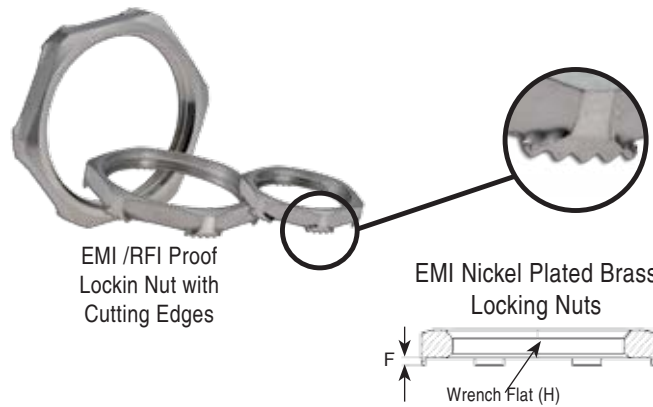



EMI/RFI - Nickel Plated Brass: Locking Nuts


Part Numbers	Thread Type & Size	Dimensions in Inches (mm)		
		G	H	F
	See page 49 for thread specs	Thickness	Wrench Flats	Cutting Edge Height
NPB w/ Cutting Edges				
NP-07-BE	PG 7	.11 (2.8)	.59 (15)	.028 (0.7)
NP-09-BE	PG 9	.11 (2.8)	.71 (18)	.028 (0.7)
NP-11-BE	PG 11	.12 (3)	.83 (21)	.028 (0.7)
NP-13-BE	PG 13 / 13.5	.12 (3)	.91 (23)	.028 (0.7)
NP-16-BE	PG 16	.12 (3)	1.02 (26)	.028 (0.7)
NP-21-BE	PG 21	.14 (3.5)	1.26 (32)	.028 (0.7)
NP-29-BE	PG 29	.16 (4)	1.61 (41)	.028 (0.7)
NP-36-BE	PG 36	.20 (5)	2.01 (51)	.028 (0.7)
NP-42-BE	PG 42	.20 (5)	2.36 (60)	.028 (0.7)
NP-48-BE	PG 48	.22 (5.5)	2.52 (64)	.028 (0.7)
NN-13-BE	1/2" NPT	.12 (3)	.94 (24)	.028 (0.7)
NM-12-BE	M12 x 1.5	.11 (2.8)	.59 (15)	.028 (0.7)
NM-16-BE	M16 x 1.5	.11 (2.8)	.75 (19)	.028 (0.7)
NM-20-BE	M20 x 1.5	.12 (3)	.94 (24)	.028 (0.7)
NM-25-BE	M25 x 1.5	.14 (3.5)	1.18 (30)	.028 (0.7)
NM-32-BE	M32 x 1.5	.18 (4.5)	1.42 (36)	.028 (0.7)
NM-40-BE	M40 x 1.5	.20 (5)	1.81 (46)	.028 (0.7)
NM-50-BE	M50 x 1.5	.20 (5)	2.36 (60)	.028 (0.7)
NM-63-BE	M63 x 1.5	.24 (6)	2.76 (70)	.028 (0.7)

These Locking Nuts have cutting edges which will slice through paint coatings on a metal enclosure to ensure grounding. Also, these Locking Nuts are suitable for vibrating applications.




Zinc Plated Steel: Locking Nuts

Part Numbers	Thread Type & Size	Dimensions in Inches (mm)	
		G	H
	See page 49 for thread specs	Thickness	Wrench Flats
Zinc Plated Steel			
NN-10-ST	1" NPT	.24 (6)	1.73 (44)
NN-34-ST	1-1/4" NPT	.20 (5)	2.01 (53)
NN-36-ST	1-1/2" NPT	.16 (4)	2.19 (55.5)

 


Note: BE-Locknuts have the following approvals: CE & German Lloyd.

(303) Stainless Steel: Locking Nuts

Part Numbers	Thread Type & Size	Dimensions in Inches (mm)	
		G	H
	See page 49 for thread specs	Thickness	Wrench Flats
(303) Stainless Steel			
NP-07-SS	PG 7	.11 (2.8)	.67 (17)
NP-09-SS	PG 9	.11 (2.8)	.87 (22)
NP-11-SS	PG 11	.12 (3)	.87 (22)
NP-13-SS	PG 13 / 13.5	.12 (3)	.94 (24)
NP-16-SS	PG 16	.12 (3)	1.06 (27)
NP-21-SS	PG 21	.14 (3.5)	1.26 (32)
NP-29-SS	PG 29	.16 (4)	1.61 (41)
NP-36-SS	PG 36	.20 (5)	1.97 (50)
NM-12-SS	M12 x 1.5	.11 (2.8)	.59 (15)
NM-16-SS	M16 x 1.5	.11 (2.8)	.75 (19)
NM-20-SS	M20 x 1.5	.12 (3)	.95 (24)
NM-25-SS	M25 x 1.5	.14 (3.5)	1.18 (30)
NM-32-SS	M32 x 1.5	.14 (3.5)	1.42 (36)
NM-40-SS	M40 x 1.5	.20 (5)	1.81 (46)
NM-50-SS	M50 x 1.5	.20 (5)	2.24 (57)
NM-63-SS	M63 x 1.5	.24 (6)	2.76 (70)

 Stainless Steel Locking Nuts



Typical Applications for Stainless Steel:

- Off-shore
- Marine
- Chemical Plants
- Food Processing
- Clean Room
- Other Rugged Applications

For Material Specifications and Approval Information, please refer to page 45.