


| PART NUMBERS | | THREAD TYPE AND SIZE For thread specs see page 29 | DIMENSIONS INCHES (MM) | |
|----------------------|----------------------|--|------------------------|------------------------|
| Black | Gray | | G Thickness | H Wrenching Flats |
| NM-12-BK NP-07-BK | NM-12-GY NP-07-GY | M12 X1,5 PG 7 / 1/4" NPT | .20 (5) .20 (5) | .67 (17) .75 (19) |
| NP-09-BK NN-09-BK | NP-09-GY -- | PG 9 3/8" NPT | .24 (6) .27 (7) | .91 (23) .94 (24) |
| NM-16-BK NP-11-BK | NM-16-GY NP-11-GY | M16 x 1,5 PG 11 | .20 (5) .20 (5) | .87 (22) .94 (24) |
| NM-20-BK NP-13-BK | NM-20-GY NP-13-GY | M20 x 1,5 PG 13,5 | .24 (6) .24 (6) | 1.06 (27) 1.06 (27) |
| NN-13-BK NP-16-BK | NN-13-GY NP-16-GY | 1/2" NPT PG 16 | .24 (6) .24 (6) | 1.06 (27) 1.18 (30) |
| NM-25-BK | NM-25-GY | M25 x 1,5 | .28 (7) | 1.42 (36) |

| PART NUMBERS | | THREAD TYPE AND SIZE For thread specs see page 29 | DIMENSIONS INCHES (MM) | |
|----------------------|----------------------|--|------------------------|------------------------|
| Black | Gray | | G Thickness | H Wrenching Flats |
| NP-21-BK NN-21-BK | NP-21-GY | PG 21 3/4" NPT | .27 (7) .27 (7) | 1.41 (36) 1.26 (32) |
| NM-32-BK NP-29-BK | NM-32-GY NP-29-GY | M32 x 1,5 PG 29 | .28 (7) .27 (7) | 1.61 (41) 1.81 (46) |
| NN-29-BK NM-40-BK | NM-40-GY | 1" NPT M40 x 1,5 | .27 (7) .28 (7) | 1.57 (40) 1.97 (50) |
| NP-36-BK NM-50-BK | NP-36-GY NM-50-GY | PG 36 M50 x 1,5 | .31 (8) .31 (8) | 2.36 (60) 2.36 (60) |
| NP-42-BK NP-48-BK | NP-42-GY NP-48-GY | PG 42 PG48 | .31 (8) .31 (8) | 2.56 (65) 2.76 (70) |
| NM-63-BK | NM-63-GY | M63 x 1,5 | .31 (8) | 2.95 (75) |

See pages 4-11 for the Nylon Product Line. To specify fittings with Locking Nut in one part number add "-N" to the connector number. **Example:** CD13NA-BK-N (product will still be invoiced separately).

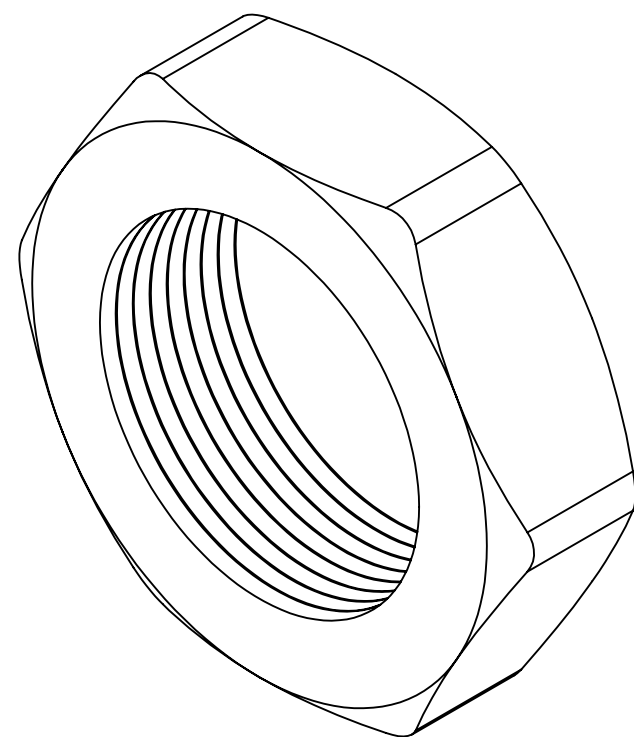

NOTES:

- 1) GENERAL DIMENSIONS DRAWINGS.
- 2) DIMENSIONS [] ARE IN INCHES.
- 3) DIMENSIONS NOTED ARE FOR REFERENCE ONLY.

| | | |
|---|--|--|
| Third angle projection | | |
| 14853 HINDSDALE AVE, SUITE D CENTENNIAL, CO 80112-4240, USA TEL: +1-303-699-1135 TOLL FREE: +1-800-456-9012 E MAIL: info@sealconusa.com , WEBSITE: www.sealconusa.com | | |
| | | |