

L 207 200 Power connectors

► Expert Range - Screw clamp connection




Female plug.

Modular mounting (panel or through panel mounting).

Body : UL94 V0 - PC

Grey ☐

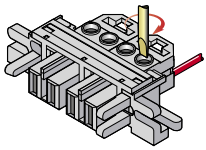

4 mm² - Spacing 7.62 mm .300"

Ordering details

N. Poles	Weight kg	Packaging	L. mm	Order code
Without flange :				
4	0.0191	30	39.90	1SSA 207 204 R0000
6	0.0287	20	55.10	1SSA 207 206 R0000
8	0.0383	20	70.40	1SSA 207 208 R0000

Other numbers of poles, consult us

With flanges :				
4	0.0191	30	59.70	1SSA 207 204 R3000
6	0.0287	20	74.90	1SSA 207 206 R3000
8	0.0383	20	90.20	1SSA 207 208 R3000



Other numbers of poles, consult us



Technical data

		IEC	UL	CSA
Wire size	Screw			
	Solid wire	4 mm ²	22 - 12 AWG	20 - 12 AWG
	Stranded wire With ferrule	4 mm ²	22 - 12 AWG	20 - 12 AWG
Rated voltage		380 V	300 V	300 V
Rated current		25 A	15 A	20 A
Short-circuit current				
Rated wire size / Gauge		4 mm ²	12 AWG	12 AWG
Storage temperature range		-20 ~ +80 °C		
Insulation resistance		≥ 10 ⁹ Ω		
Wire stripping length		10 mm / .394"		
Recommended screwdriver		3.5 mm / .138"		
Recommended torque		0.6 Nm / 5.3 lb.in		
Protection		IP 20 / NEMA 1		

Plug L 207 200
compatible with :

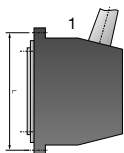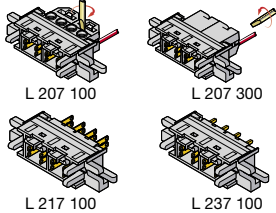


Accessories

Rep.	Description	Type	Order code	L. mm	Packaging	Weight kg
1	Housing	grey ☐	4 poles	1SSA 299 004 R0100	50.30 mm	
		grey ☐	6 poles	1SSA 299 004 R0200	65.50 mm	
		grey ☐	8 poles	1SSA 299 004 R0300	80.80 mm	

Other versions, please consult us :

 Female plug. Wire Wrapping.



L 227 200

