


POWER DISTRIBUTION

AMPINENERGY


Cable Assemblies

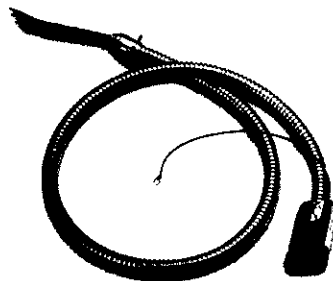


8-Wire Power Entry Cable Assemblies

Description	Length cm(in)	Part Number
10/12 AWG Neutrals 15.24 cm (6.00 in) Exposed Conductor	40.64 (16)	1-555856-0
	60.96 (24)	555856-1
	91.44 (36)	555856-2
	121.92 (48)	555856-3
	152.40 (60)	555856-8
	182.88 (72)	555856-4
	213.36 (84)	1-555856-5
	243.84 (96)	1-555856-1
	304.80 (120)	1-555856-4
	335.28 (132)	555856-9
	365.76 (144)	555856-5
	457.20 (180)	1-555856-3
	548.64 (216)	555856-6
	609.60 (240)	1-555856-6
	762.00 (300)	555856-7
10/10 AWG Neutrals	1524.00 (600)	1-555856-2
	121.92 (48)	558058-8*
	152.40 (60)	558058-7*
	182.88 (72)	558058-9*
	243.84 (96)	1-558058-3*
	762.00 (300)	1-558058-2*
	1524.00 (600)	558058-1*
	With 90° Conduit Connector on Black Painted Conduit, 10/10 AWG Neutrals	112.96 (48)
		558462-1*
		1524.00 (600)
121.92 cm (48.00 in) Exposed Conductor		558462-2*
		762.00 (300)
		406066-3
10/12 AWG Neutrals	1066.80 (420)	406066-2
	1524.00 (600)	406066-1

*Note: Two 5.29 mm² [10 AWG] Neutrals are available for 50/50 power on special order for all cable assemblies.

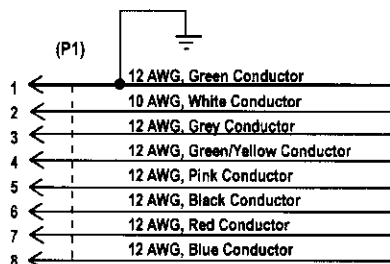

Wiring Diagram for
555856 and 406066

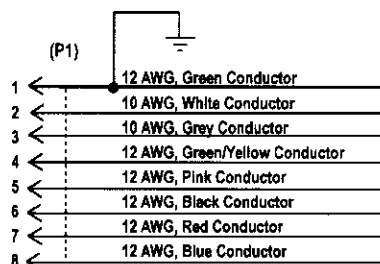

Wiring Diagram for
558462 and 558058