





# Omnimate Range - 5.08 mm Pitch

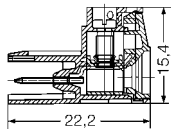

## Pin plugs SLS 5.08/180

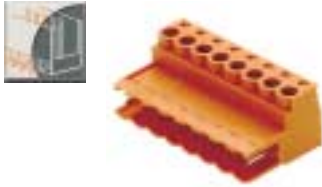

## Pin plugs SLS 5.08/180B

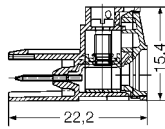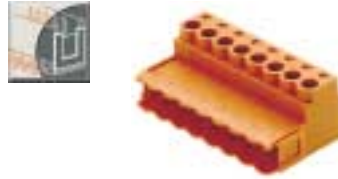

Technical data	VDE	UL	CSA
<b>Rated voltage (V)</b>	250*	300	300
<b>Rated current (A)</b>	12	15	14
<b>Wire size (mm<sup>2</sup>/AWG)</b>	2.5	28...12	28...12

\*Pollution severity 3 / Overvoltage category III

Additional technical data see page 223

Technical data	VDE	UL	CSA
<b>Rated voltage (V)</b>	250*	300	300
<b>Rated current (A)</b>	12	15	14
<b>Wire size (mm<sup>2</sup>/AWG)</b>	2.5	28...12	28...12

\*Pollution severity 3 / Overvoltage category III

Additional technical data see page 223

### Color



Poles	Type	Part No.	Part No.	Qty.
2	SLS 5.08/2/180	1627090000	1644920000	100
3	SLS 5.08/3/180	1627100000	1644930000	100
4	SLS 5.08/4/180	1627110000	1644940000	100
5	SLS 5.08/5/180	1627120000	1644950000	50
6	SLS 5.08/6/180	1627130000	1644960000	50
7	SLS 5.08/7/180	1627140000	1644970000	50
8	SLS 5.08/8/180	1627150000	1644980000	50
9	SLS 5.08/9/180	1627160000	1644990000	50
10	SLS 5.08/10/180	1627170000	1645000000	50
11	SLS 5.08/11/180	1627180000	1645010000	50
12	SLS 5.08/12/180	1627190000	1645020000	50
13	SLS 5.08/13/180	1627200000	1645030000	50
14	SLS 5.08/14/180	1627210000	1645040000	50
15	SLS 5.08/15/180	1627220000	1645050000	50
16	SLS 5.08/16/180	1627230000	1645060000	50
17	SLS 5.08/17/180	1644840000	1645070000	20
18	SLS 5.08/18/180	1644850000	1645080000	20
19	SLS 5.08/19/180	1644860000	1645090000	20
20	SLS 5.08/20/180	1644870000	1645100000	20
21	SLS 5.08/21/180	1644880000	1645110000	20
22	SLS 5.08/22/180	1644890000	1645120000	20
23	SLS 5.08/23/180	1644900000	1645130000	20
24	SLS 5.08/24/180	1644910000	1645140000	20

Accessories	Page
Mounting	-
Marking	190
Coding	192, 193
Miscellaneous	195-201

### Color



Poles	Type	Part No.	Part No.	Qty.
2	SLS 5.08/2/180B	1627240000	1645230000	100
3	SLS 5.08/3/180B	1627250000	1645240000	100
4	SLS 5.08/4/180B	1627260000	1645250000	100
5	SLS 5.08/5/180B	1627270000	1645260000	50
6	SLS 5.08/6/180B	1627280000	1645270000	50
7	SLS 5.08/7/180B	1627290000	1645280000	50
8	SLS 5.08/8/180B	1627300000	1645290000	50
9	SLS 5.08/9/180B	1627310000	1645300000	50
10	SLS 5.08/10/180B	1627320000	1645310000	50
11	SLS 5.08/11/180B	1627330000	1645320000	50
12	SLS 5.08/12/180B	1627340000	1645330000	50
13	SLS 5.08/13/180B	1627350000	1645340000	50
14	SLS 5.08/14/180B	1627360000	1645350000	50
15	SLS 5.08/15/180B	1627370000	1645360000	50
16	SLS 5.08/16/180B	1627380000	1645370000	50
17	SLS 5.08/17/180B	1645150000	1645380000	20
18	SLS 5.08/18/180B	1645160000	1645390000	20
19	SLS 5.08/19/180B	1645170000	1645400000	20
20	SLS 5.08/20/180B	1645180000	1645410000	20
21	SLS 5.08/21/180B	1645190000	1645420000	20
22	SLS 5.08/22/180B	1645200000	1645430000	20
23	SLS 5.08/23/180B	1645210000	1645440000	20
24	SLS 5.08/24/180B	1645220000	1645450000	20

Accessories	Page
Mounting	187
Marking	190
Coding	192, 193
Miscellaneous	195-201