

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1121115001](#)
Status: **Active**
Overview: [Brad® Industrial Ethernet Solutions](#)
Description: Direct-Link® Industrial 5-Port, IP67 (Machine Mount) Ethernet Switch, Unmanaged, 5-pole M12 Ultra-Lock®, 10/100 Mb/s

Documents:
[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Switches
Series [112111](#)
Approvals CE certified, UL (pending)
Comments 2.0W (24VDC)
IP Rating IP67
MAC Address N/A
Overview [Brad® Industrial Ethernet Solutions](#)
Product Literature Order No 987650-5646
Product Name Direct-Link®
Protocol EtherNet (IEEE 802.3)
Switch Functionality Unmanaged
Type N/A
UPC 883906689483
Woodhead Yes

Physical
Ethernet Connector 4-Pole Ultra-Lock® (M12) Conn
Housing Width 30.00mm
Mechanical Shock 50G (IEC 68-2-29)
Mounting Style N/A
Net Weight 0.220/kg
Packaging Type Carton
Ports 5
Power Input 5-pole Micro-Change® (M12)
Temperature Range - Operating -40°C to +75°C
Uplink Connection 5-Pole Micro-Change® (M12)
Vibration 7g (IEC 68-2-29)

Electrical
Current - Maximum Output N/A
EMC EN 61000-4-2, EN 61000-4-4, EN 61000-4-5, EN 61326
Supply Voltage 2.0W (24V DC)

Material Info
Engineering Number DRL-750

Reference - Drawing Numbers
Sales Drawing 1121115001-000, DRL-7*0

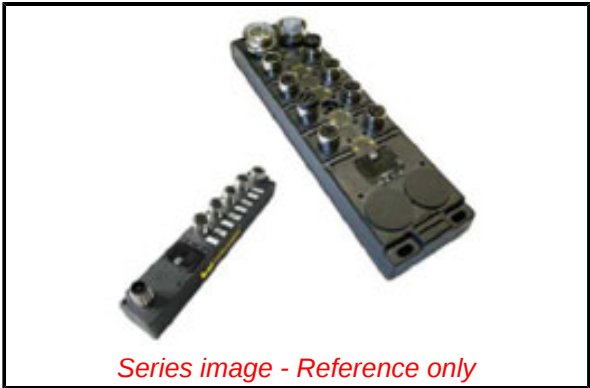

EU ELV
Not Relevant

EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Low-Halogen	
Need more information on product environmental compliance?	

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[112111](#) Series