

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1200980089](#)  
**Status:** **Active**  
**Overview:** Brad Micro-Change (M12) Connectors  
**Description:** Micro-Change (M12) Single-Ended Cordset, 5 Poles, Female (Straight) to Pigtail, 24 AWG, 10.0m (32.81') Length, PROFIBUS PUR Cable Preferred Version in Europe

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Industrial Cordsets
Series	<a href="#">120098</a>
Connector End A	Micro-Change (M12)
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	<a href="#">Brad Micro-Change (M12) Connectors</a>
Product Name	Micro-Change (M12)
Protocol	EtherNet
Region	America
Type	Single Ended
UPC	78678852055

**Physical**

Cable Diameter	8.00mm (.315")
Cable Length	10.0m (32.81')
Color - Cable Jacket	Yellow
Coupling Style	Threaded
Gender	Female-Pigtail
Keyway	Reverse
LED Indicator	No
Material - Cable Jacket	PUR
Material - Connector Body	PUR
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold over Nickel
Net Weight	777.008/g
Orientation	Straight to Pigtail
Poles	5
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	24
Wire/Cable Type	Twisted Pair

**Electrical**


Current - Maximum per Contact	4.0A
Voltage - Maximum	60V AC/DC

**Material Info**

Engineering Number	B05S00PP4M100
--------------------	---------------

**Reference - Drawing Numbers**

Sales Drawing	SD-120098-039
---------------	---------------

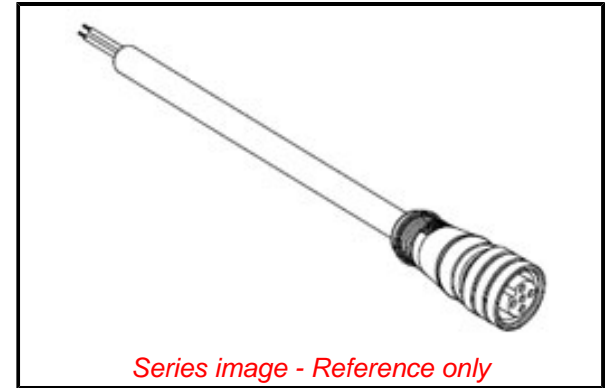

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant with Exemption 6(c)**

**REACH SVHC**

Not Contained Per - ED/30/2017 (7 July 2017)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

**Search Parts in this Series**

[120098 Series](#)