

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300340006](#)
Status: **Active**
Overview: [Brad Mini-Change Connectors](#)
Description: Mini-Change Trunk Connector, Threaded, Single Keyway, Straight Male, 5 Poles

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Field Attachable / Accessories
Series [130034](#)
IP Rating IP67
Material - Contact Copper Alloy
Overview [Brad Mini-Change Connectors](#)
Product Name Mini-Change
Type Field Attachable Connector
UPC 78172553490

Physical

Cable Diameter N/A
Coupling Type External Thread
Diagnostics / LEDs No
Diagnostics Port No
Gender Male
Keyway Single
Material - Connector Body Polyamide
Material - Coupling Nut Nickel-plated Brass
Material - Plating Mating n/a
Net Weight 159.000/g
Orientation Straight
Poles 5
Temperature Range - Operating -25°C to +90°C
Wire Size AWG N/A

Electrical


Current - Maximum per Contact 4.0A
Voltage - Maximum 36V

Material Info

Engineering Number 1A5006-34DN

Reference - Drawing Numbers

Sales Drawing SD-130034-002

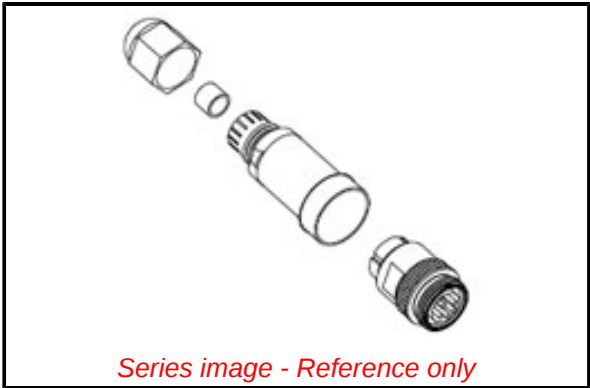

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - ED/71/2019 (16 July 2019)

Lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[130034](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION