

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1301350219

Status:


Active

Overview:

Outlet Boxes

Description:

Super-Safeway GFCI Multiple Outlet Box with Ground Continuity Monitor, Open Neutral Relay, (2) NEMA 5-20 Duplex with Flip Lids, 0.305m (1.0') Cord Length, 12/3 SOOW Cord, NEMA 5-20 Plug

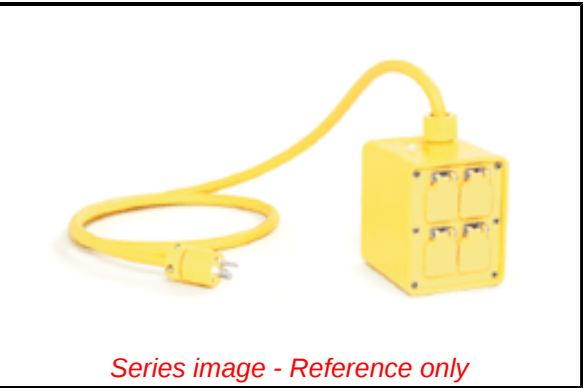

Documents:

RoHS Certificate of Compliance (PDF)

Product Literature (PDF)

General	
Product Family	Power Distribution
Series	130135
Enclosure Rating	NEMA 4
Exclude SD Check	Yes
GFCI Reset	Manual
Mounting Style	Portable
Open Neutral Relay	Yes
Overview	Outlet Boxes
Product Literature Order No	987650-7737
Product Name	Super-Safeway
Receptacle Type	Duplex
Type	GFCI Multiple Outlet Box
UPC	78678876132
Physical	
Cord Diameter	15.24mm (.600")
Cord Grip Body Size	F3 3/4"
Cord Length	0.305m (1.0')
Feed-Thru	No
Flip Lid	Yes
Material - Housing	Rubber
Number of Receptacles	2
Packaging Type	Carton
Electrical	
Cord Type	12/3 SOOW
Current - Maximum per Contact	20.0A
GFCI	Yes
Ground Continuity Monitor	Yes
NEMA Configuration	NEMA 5-20
Voltage - Maximum	N/A
Material Info	
Engineering Number	32GM20E123

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Relevant	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

130135 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION