

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1210120107](#)
Status: **Active**
Overview: [mPm® DIN Valve Connectors](#)
Description: mPm® DIN Base, Form B - Industrial, B29 Base, 3 Pole Plus Ground Terminal, 250V AC/300V DC, Black Nitrile Gasket with Screws

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification PK-121012-B29-001 \(PDF\)](#)


General
Product Family Field Attachable / Accessories
Series [121012](#)
Form B - Industrial
IP Rating IP65, IP67
Material - Contact Brass
Overview [mPm® DIN Valve Connectors](#)
Product Name mPm®
Type Field Attachable Connector
UPC 883906248758

Physical
Cable Diameter N/A
Coupling Type N/A
Diagnostics / LEDs No
Diagnostics Port No
Gender N/A
Keyway None
Material - Connector Body Polypropylene
Material - Coupling Nut N/A
Material - Plating Mating Tin
Net Weight 7.603/g
Orientation Straight
Pitch - Mating Interface 11.00mm
Poles 3
Temperature Range - Operating -40°C to +90°C
Wire Size AWG N/A

Electrical
Current - Maximum per Contact 10.0A
Voltage - Maximum 250V AC / 300V DC

Material Info
Engineering Number B293000N2

Reference - Drawing Numbers
[Packaging Specification](#) PK-121012-B29-001
[Sales Drawing](#) SD-121012-007

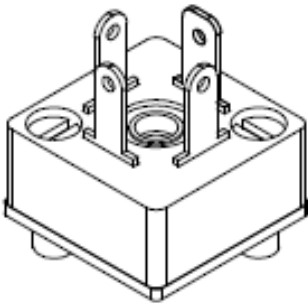

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Not Contained Per - ED/30/2017 (7 July 2017)	
Halogen-Free Status	
Low-Halogen	
Need more information on product environmental compliance?	
Email productcompliance@molex.com	
Please visit the Contact Us section for any non-product compliance questions.	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[121012 Series](#)