

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130010-0226](#)
Status: **Active**
Overview: Brad® Mini-Change® Connectors
Description: Mini-Change® A-Size Double-Ended Cordset, 3 Poles, Male (Straight) to Female (Straight), 16 AWG, PVC Cable, 2.74m (9.0') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E152210

General

Product Family Industrial Cordsets
 Series [130010](#)
 Connector End A Mini-Change®
 Connector End B Mini-Change®
 IP Rating IP67
 Overview [Brad® Mini-Change® Connectors](#)
 Product Name Mini-Change®
 Protocol N/A
 Region America
 Type Double Ended
 UPC 78678842883

Physical

Cable Diameter 10.41mm (.410")
 Cable Length 2.74m (9.0')
 Color - Cable Jacket Yellow
 Coupling Style Threaded
 Gender Male-Female
 Keyway Single
 LED Indicator No
 Material - Cable Jacket PVC
 Material - Connector Body PVC
 Material - Contact Copper Alloy
 Material - Coupling Nut Black Epoxy Coated Zinc
 Material - Plating Mating Gold over Nickel
 Net Weight 750.240/g
 Orientation Straight
 Poles 3
 Temperature Range - Operating -20°C to +105°C
 Wire Size AWG 16
 Wire/Cable Type ST00W

Electrical

Current - Maximum per Contact 13A
 Voltage - Maximum 600V

Material Info

Old Part Number 113020A01F090

Reference - Drawing Numbers

Sales Drawing SD-130010-002

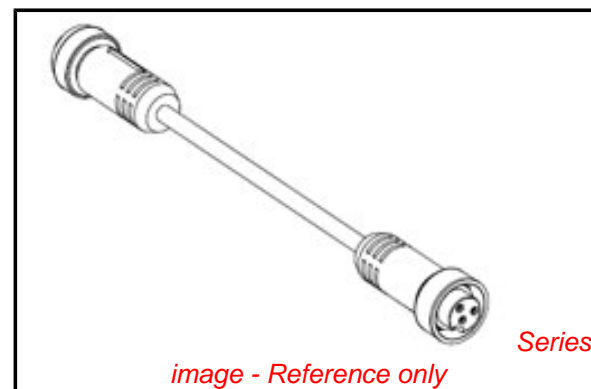


image - Reference only

EU RoHS

RoHS Compliant by Exemption

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

130010Series

This document was generated on 10/20/2014

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION