



# C&K<sup>®</sup>

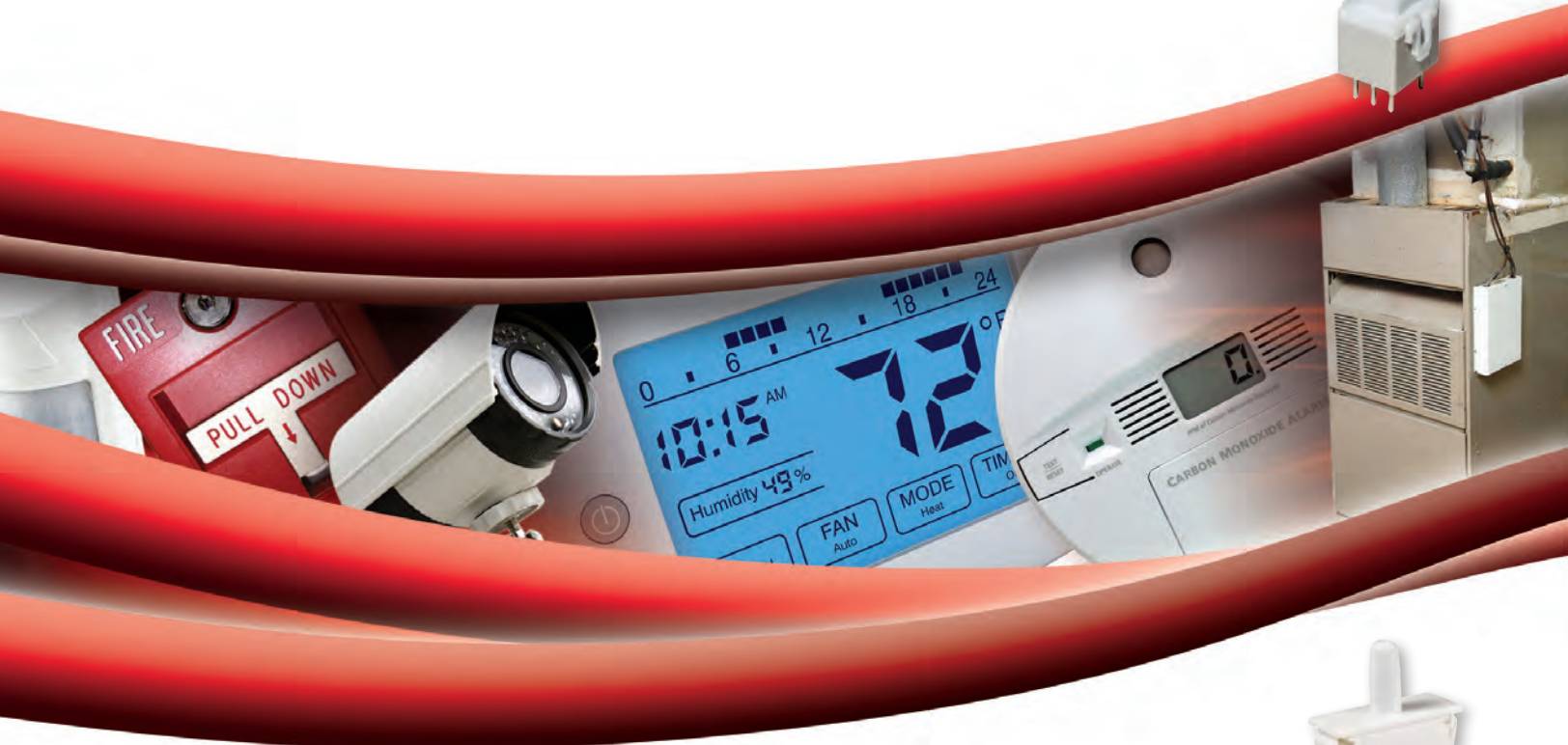

## SWITCH SOLUTIONS FOR BUILDING AND HOME AUTOMATION APPLICATIONS

[www.ck-components.com](http://www.ck-components.com)

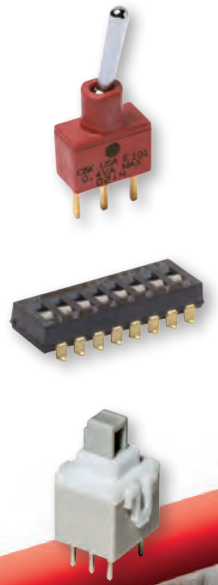

# DESIGNING TECHNOLOGY INTO SOLUTIONS

		DIP / Coded Rotary	Slide	Tact	Snap	Detect	Toggle	Pushbutton / Keypad	Keylock
	Smoke / CO Detectors	•	•	•		•		•	
	Intrusion Alarms	•		•		•			•
	Building Access Controls	•		•	•		•	•	•
	Automatic Gates	•		•	•				
	Video Security	•		•		•			•
	Elevator Controls	•		•	•		•	•	•
	Programmable Thermostats	•	•	•		•			
	HVAC Control Boards	•	•	•					
	HVAC Air Dampers	•			•				
	Furnace, Boiler, Aircon Systems				•				
	Wall Heaters	•	•	•	•			•	
	Tankless Water Heaters	•		•	•			•	
	HVAC Zone Controls	•	•	•					
	Lighting Controllers		•	•				•	
	Occupancy Sensors	•	•	•					
	Shutter & Blind Controllers	•		•	•				
	Circuit Breakers	•		•	•	•		•	
	Energy Meters			•		•		•	
	Nurse Call Systems	•		•				•	•

## SAFETY AND SECURITY



- Smoke & carbon monoxide alarms
- Fire alarm systems
- Intrusion alarms & security systems
- Security cameras & controllers
- Building intercom systems
- Automatic gates and doors
- Elevator controls
- Nurse call systems

Performance, reliability, and durability are key requirements when it comes to keeping residential and commercial buildings safe, comfortable, and energy efficient. Home owners and building managers expect their HVAC, lighting, and safety & security systems to function reliably around the clock.

C&K products, with their reputation for high quality and long cycle life, are ideally suited for demanding applications in harsh environments. By working directly with customers, C&K provides application specific, custom solutions to our customer's most challenging requirements.



## HVAC & ENERGY MANAGEMENT

- Furnaces & air handler units
- HVAC control boards
- Wall mounted heaters
- Programmable thermostats
- Air dampers & zone controls
- Tankless water heaters
- Energy meters, timers, & relays
- Circuit breakers
- Boiler controls
- Domotics controllers & keypads
- Solar inverters




	APPLICATION	FUNCTION	SWITCHES
SAFETY & SECURITY	Smoke alarm	Test & reset buttons	Tact, Slide, Detect
	Smoke alarm	Node / network address identification	DIP, Detect
	Carbon monoxide alarm	Test & reset buttons	Tact, Pushbutton
	Glass break detector	Test button, sensitivity settings	Tact, DIP, Rotary DIP
	Glass break detector	Node / network address identification	Rotary DIP
	Shock sensor (ATM's)	Mode select (safe / vault / ATM)	DIP
	Fire / intrusion alarm (relay module)	Node / network address identification	DIP
	Fire / intrusion alarm (relay module)	Cover tamper switch	Tact, Detect
	Fire alarm / zone expansion module	Node / network address identification	DIP, Switchlock
	Fire alarm / communicator module	Mode switch, cover tamper switch	Tact
	Fire alarm pull switch	Pull switch position	Toggle, Snap
	Door intercom systems	Intercom call buttons	Tact or pushbutton
	Door / telephone entry systems	Configuration switch	DIP
	Door / telephone entry systems	Master code program switch	Toggle
	Fire doors / automatic doors	Door latch / strike position	Snap
	Gate openers	Code entry / open & close buttons	Pushbutton
	Gate openers / card access module	Master code program / reset switch	Tact
	Lift gate controllers	Gate operation settings	DIP
	Lift gate controllers	Manual gate cycle button	Tact
	Sliding gate openers	Gate open / closed limit switches	Snap
Commercial garage door openers	Door position remote controls	Snap, DIP	
Nurse call systems (hospital)	Call / cancel switch, corner light / room ID	Tact, DIP, Pushbutton	
Security cameras (PTZ)	Camera node / network ID	DIP, Switchlock	
Security cameras (PTZ)	Camera settings (baud rate, protocol)	DIP	
IR security cameras	IR light level settings	DIP	
Highway / road / traffic cameras	Menu navigation switches	Tact	
DVR, security cameras	Function buttons, navigation switch	Tact, Navigation	
Joystick controller, security camera	Function / navigation buttons	Tact, Navigation	
Elevators	Floor selection	Tact or Pushbutton	
Elevators	Maintenance / fire lockout	Switchlock	
Elevators	Main control board, top of car (TOC) controller	Toggle, Rotary DIP, Tact	
Elevators	Door open / closed limit switch	Snap	
HVAC	Furnace / aircon control boards	Fan settings, gas ignition settings, fault recall	DIP, Tact
	Programmable thermostats	Temperature up / down settings, reset button	Tact
	Programmable thermostats	On / off, gas / electric heat select, fan speed	Slide
	Air handler / VAV units	Controller settings	DIP, Rotary DIP
	Terminal unit / air dampers	Damper position, damper settings	Snap, Rotary DIP
	Furnace / Air handler units	Blower / fan door safety switch	Snap
	Wall heater (condensing boilers)	On / off button, temperature select	Slide, Tact, Keypad
	Wall heater (condensing boilers)	Control board / heater settings	DIP, Rotary DIP, Keypad
	Tankless water heaters	Programming keys, heater settings	Tact, DIP, Keypad
	Lighting timers, switches	On / off switch, programming buttons	Slide, Tact
LIGHTING	Shutter & blind controllers	Auto / manual select, open / close buttons	Slide, Tact
	Occupancy sensors	Day / night selection, sensitivity settings	Slide, DIP
	Lighting timers, switches	On / off switch, programming buttons	Slide, Tact
	Shutter, shade, & blind motors	Position switch	Snap
	Shutter & blind controllers	Auto / manual select, open / close buttons	Slide, Tact
Shutter & blind controllers	Receiver unit settings, node address ID	Tact, DIP	

## LIGHTING

- Occupancy sensors
- Lighting controllers
- Timers & relays
- Programmable switches
- Shutter & blind controllers





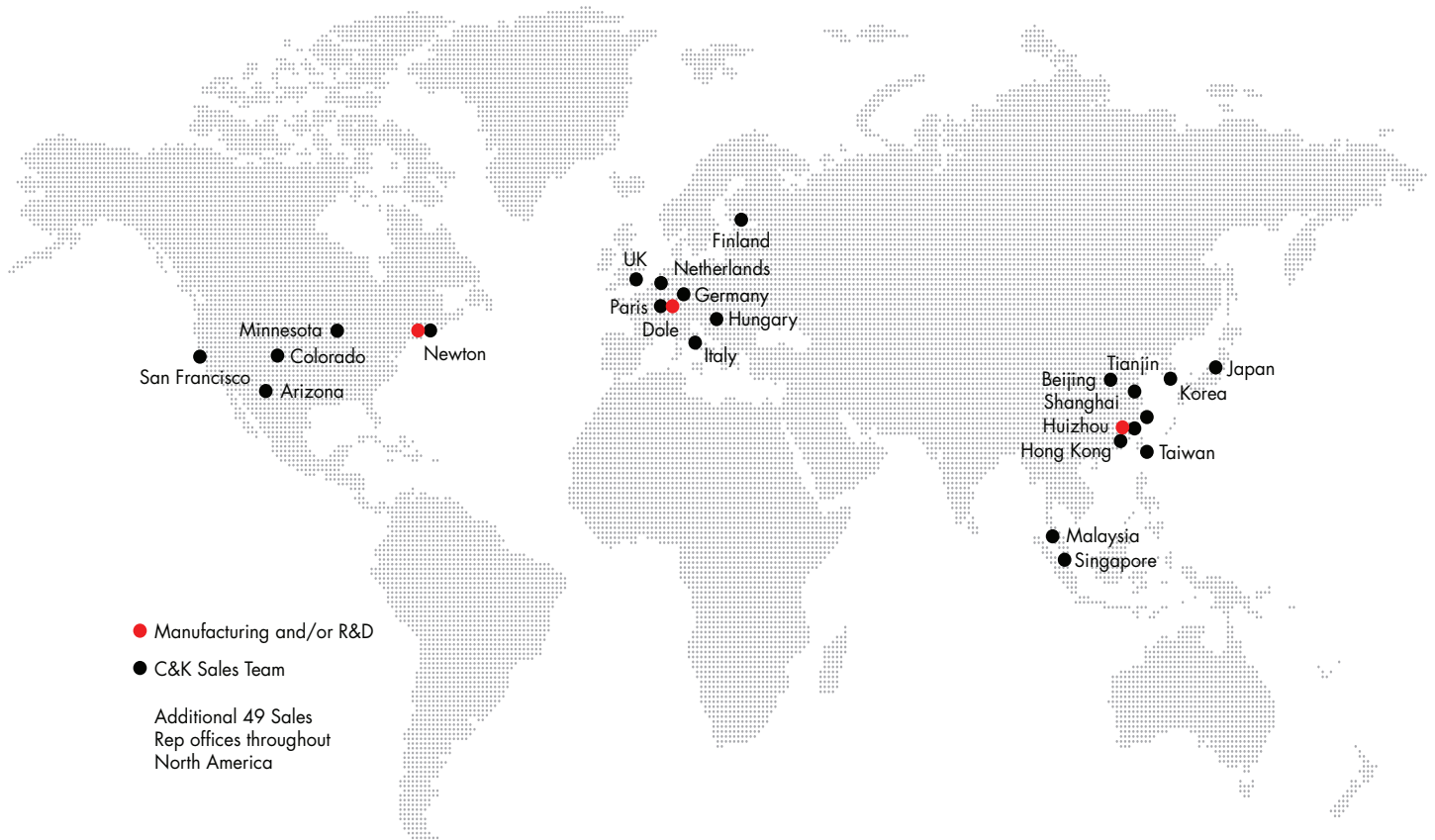

Please visit [www.ck-components.com](http://www.ck-components.com) to view C&K's full product offering and list of partners and distributors. The "Ask a specialist" function on the website allows direct contact to each C&K product manager to leverage your C&K product knowledge.

**AMERICAS**

Tel: +1.617.969.3700

**FRANCE**

Southern and Western Europe

Tel: +33.1.60.24.51.51

**GERMANY**

Central and Eastern Europe & Nordic

Tel: +49.30.814.539.250

**HONG KONG**

Tel: +852.3713.5288

**SHANGHAI**

Tel: +86.21.5413.0137

