


# SWITCHES STANDARD TOGGLE

## HEAVY DUTY UTILITY BAT HANDLE TOGGLE SWITCH (Two Circuit)

### SPECIFICATIONS:

<b>Current Rating:</b>	20A @125V AC, 10A @ 250V AC 1-1/2 HP @ 125-250V AC
<b>Initial Contact Resistance:</b>	50 Meg ohm (Max.)
<b>Insulation Resistance:</b>	100 Meg ohm (Min.) @ 500V DC
<b>Dielectric Strength:</b>	1000V AC 50/60 Hz for 1 minute
<b>Contact Material:</b>	Brass - Nickel Plate
<b>Terminal Material:</b>	Brass
<b>Terminal Type:</b>	Screw

Part No.	Type	Action			Actuator
30-135	SP3T	ON	ON	ON	Metal

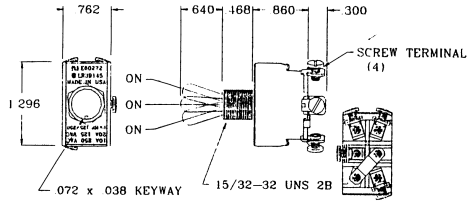

Mounting Hole: 0.500"

ON (2+6)  
ON (2+4)  
ON (1+4)

Mounting Hole: 0.500"




### SPECIFICATIONS:

<b>Current Rating:</b>	20A @125V AC, 10A @ 277V AC 3/4 HP @ 125-250V AC
<b>Initial Contact Resistance:</b>	50 Meg ohm (Max.)
<b>Insulation Resistance:</b>	100 Meg ohm (Min.) @ 500V DC
<b>Dielectric Strength:</b>	1000V AC 50/60 Hz for 1 minute
<b>Contact Material:</b>	Brass - Bright Nickel Plate
<b>Terminal Material:</b>	Brass
<b>Terminal Type:</b>	.250" Quick Connect


Part No.	Type	Action			Actuator
30-300	SPST	(ON)	-	OFF	Metal
30-305	SPST	ON	-	OFF	Metal
30-310	SPDT	ON	-	ON	Metal
30-315	SPDT	ON	OFF	ON	Metal
30-335	SPDT	(ON)	OFF	(ON)	Metal

NOTE: ( ) = Momentary

## HEAVY DUTY BAT HANDLE TOGGLE SWITCHES - SPST & SPDT

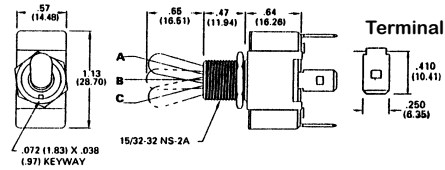

Mounting Hole: 0.500"

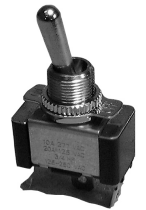


### SPECIFICATIONS:

<b>Current Rating:</b>	20A @125V AC, 10A @ 277V AC 3/4 HP @ 125/250V AC
<b>Initial Contact Resistance:</b>	50 Meg ohm (Max.)
<b>Insulation Resistance:</b>	100 Meg ohm (Min.) @ 500V DC
<b>Dielectric Strength:</b>	1000V AC 50/60 Hz for 1 minute
<b>Contact Material:</b>	Brass - Bright Nickel Plate
<b>Terminal Material:</b>	Brass
<b>Terminal Type:</b>	Screw

Part No.	Type	Action			Actuator
30-080	SPST	ON	-	OFF	Metal
30-355	SPST	(ON)	-	OFF	Metal
30-013	SPDT	ON	-	ON	Metal
30-116	SPDT	ON	-	(ON)	Metal
30-010	SPDT	ON	OFF	ON	Metal
30-053	SPDT	ON	OFF	(ON)	Metal
30-055	SPDT	(ON)	OFF	(ON)	Metal

NOTE: ( ) = Momentary

## HEAVY DUTY BAT HANDLE TOGGLE SWITCHES - SPST & SPDT

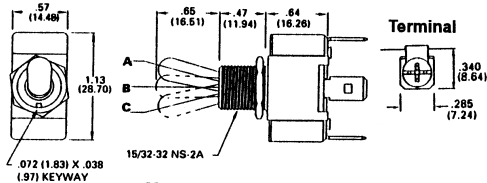

Mounting Hole: 0.500"




### SPECIFICATIONS:

<b>Current Rating:</b>	20A @ 125V AC, 10A @ 277V AC 3/4 HP @ 125-250V AC
<b>Initial Contact Resistance:</b>	50 Meg ohm (Max.)
<b>Insulation Resistance:</b>	100 Meg ohm (Min.) @ 500V DC
<b>Dielectric Strength:</b>	1000V AC 50/60 Hz for 1 minute
<b>Contact Material:</b>	Brass - Bright Nickel Plate
<b>Terminal Material:</b>	Brass - Tin Dipped
<b>Terminal Type:</b>	Solder

Part No.	Type	Action			Actuator
30-078	SPST	ON	-	OFF	Metal
30-076	SPST	(ON)	-	OFF	Metal
30-014	SPDT	ON	-	ON	Metal
30-016	SPDT	ON	-	(ON)	Metal
30-086	SPDT	ON	OFF	(ON)	Metal

NOTE: ( ) = Momentary

## HEAVY DUTY BAT HANDLE TOGGLE SWITCHES - SPST & SPDT

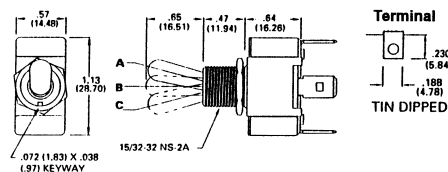

Mounting Hole: 0.500"

